


Item description/product images

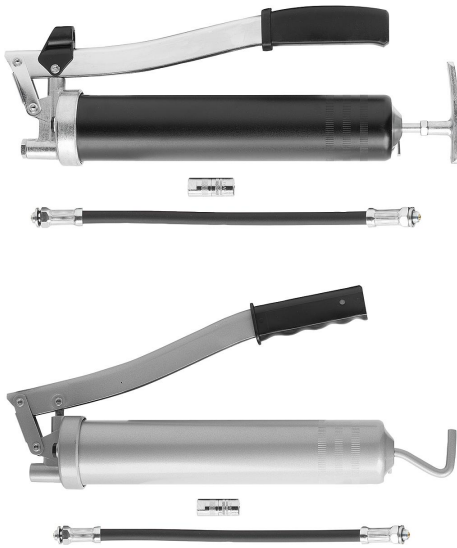

Description

Material:

Housing: steel.

Grease gun head: die-cast zinc.

Note:

DIN 1283 hand-lever grease gun for 400 g grease cartridges or 500 cm³ bulk grease. The pump piston is a precision fit in the cylinder. This prevents grease from seeping out. Quick venting by half a turn of the grease gun hose.

Supplied with reinforced hose and mouthpiece.

Overview of items

Order No.	Version 1	Version 2	Filling options	Medium
97990-11-111500	standard	for DIN 71412 conical head grease nipples	Grease cartridge, bulk grease	Grease up to NLGI 2 at 20 °C
97990-11-121500	Premium	for DIN 71413 conical head grease nipples	Grease cartridge, bulk grease, filling device	Grease up to NLGI 3 at 20 °C

Order No.	Pressure bar	Burst pressure bar	Volume per stroke cm ³	Connecting thread	Connection	Mouth piece
97990-11-111500	400 bar	850 bar	1,2	M10x1	Reinforced hose Ø8x300	Hydraulic mouthpiece
97990-11-121500	600 bar	900 bar	1,2	M10x1	Reinforced hose Ø11x300	Precision mouthpiece