

Item description/product images




Description

Material:
Steel 1.0503 (C45).

Version:
Milled tothing, straight teeth.
Engagement angle 20°, bright.
Axis angle = 90°.

Note for ordering:
Bevel gears are supplied singly. To obtain a pair of bevel gears, please order the specified mating gear as well.

Drawings

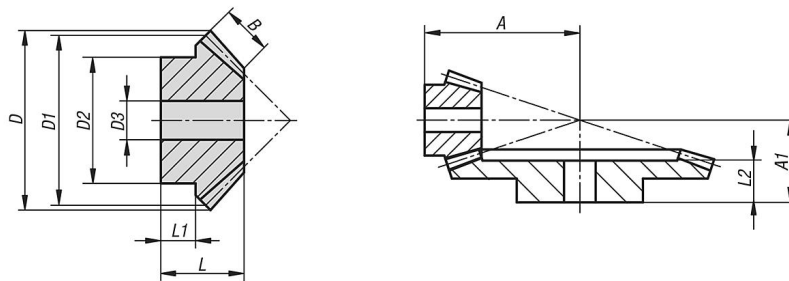

Overview of items

Order No.	Transmission ratio	Module	No. of teeth	A	A1	B	D	D1	D2	D3	L	L1	L2	matching opposing gear
22430-010130015	1:3	1	15	32	-	7,1	17,7	15	13,3	4	16,6	9,3	-	22430-010130045
22430-010130045	1:3	1	45	-	22	7,1	45,3	45	25,3	8	17,1	10	15	22430-010130015
22430-015130015	1:3	1,5	15	46	-	10,5	26,5	22,5	19,3	8	22,6	11,7	-	22430-015130045
22430-015130045	1:3	1,5	45	-	37	10,5	68,1	67,5	45,3	14	29,6	20	27	22430-015130015
22430-020130015	1:3	2	15	60	-	14	35,4	30	25,3	8	28,9	14,2	-	22430-020130045
22430-020130045	1:3	2	45	-	42	14	90,8	90	45,3	15	32,1	20	29	22430-020130015
22430-025130015	1:3	2,5	15	73	-	18	44,2	37,5	32,3	12	34,6	15,9	-	22430-025130045
22430-025130045	1:3	2,5	45	-	52	18	113,4	112,5	60,3	20	39,7	25	36	22430-025130015
22430-030130015	1:3	3	15	88	-	21	53	45	40,3	15	41,3	19,7	-	22430-030130045
22430-030130045	1:3	3	45	-	62	21	136,1	135	60,3	20	47,2	30	42,5	22430-030130015