

Item description/product images



Description

Material:

Knobs thermoset PF 31.


Rod steel 1.0718 or stainless steel 1.4305.

Version:

Thermoset black, high-gloss polished.

Steel black oxidised or bright stainless steel.

Drawings

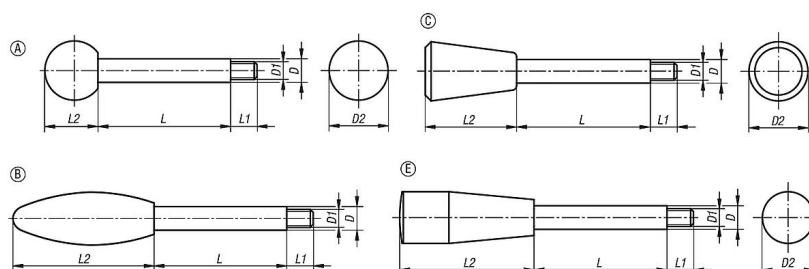

Overview of items

| Order No. | Main material | Form | D | D1 | D2 | L | L1 | L2 |
|----------------|-----------------|------|----|-----|----|-----|----|----|
| 06360-208X35 | steel | A | 8 | M6 | 20 | 35 | 9 | 18 |
| 06360-208X50 | steel | A | 8 | M6 | 20 | 50 | 9 | 18 |
| 06360-208X65 | steel | A | 8 | M6 | 20 | 65 | 9 | 18 |
| 06360-210X50 | steel | A | 10 | M8 | 25 | 50 | 13 | 23 |
| 06360-210X65 | steel | A | 10 | M8 | 25 | 65 | 13 | 23 |
| 06360-210X80 | steel | A | 10 | M8 | 25 | 80 | 13 | 23 |
| 06360-210X100 | steel | A | 10 | M8 | 25 | 100 | 13 | 23 |
| 06360-212X65 | steel | A | 12 | M10 | 32 | 65 | 15 | 29 |
| 06360-212X80 | steel | A | 12 | M10 | 32 | 80 | 15 | 29 |
| 06360-212X100 | steel | A | 12 | M10 | 32 | 100 | 15 | 29 |
| 06360-212X125 | steel | A | 12 | M10 | 32 | 125 | 15 | 29 |
| 06360-214X80 | steel | A | 14 | M12 | 36 | 80 | 16 | 33 |
| 06360-214X100 | steel | A | 14 | M12 | 36 | 100 | 16 | 33 |
| 06360-214X125 | steel | A | 14 | M12 | 36 | 125 | 16 | 33 |
| 06360-214X160 | steel | A | 14 | M12 | 36 | 160 | 16 | 33 |
| 06360-1208X35 | stainless steel | A | 8 | M6 | 20 | 35 | 9 | 18 |
| 06360-1208X50 | stainless steel | A | 8 | M6 | 20 | 50 | 9 | 18 |
| 06360-1208X65 | stainless steel | A | 8 | M6 | 20 | 65 | 9 | 18 |
| 06360-1210X50 | stainless steel | A | 10 | M8 | 25 | 50 | 13 | 23 |
| 06360-1210X65 | stainless steel | A | 10 | M8 | 25 | 65 | 13 | 23 |
| 06360-1210X80 | stainless steel | A | 10 | M8 | 25 | 80 | 13 | 23 |
| 06360-1210X100 | stainless steel | A | 10 | M8 | 25 | 100 | 13 | 23 |
| 06360-1212X65 | stainless steel | A | 12 | M10 | 32 | 65 | 15 | 29 |

Overview of items

| Order No. | Main material | Form | D | D1 | D2 | L | L1 | L2 |
|----------------|-----------------|------|----|-----|----|-----|----|----|
| 06360-1212X80 | stainless steel | A | 12 | M10 | 32 | 80 | 15 | 29 |
| 06360-1212X100 | stainless steel | A | 12 | M10 | 32 | 100 | 15 | 29 |
| 06360-1212X125 | stainless steel | A | 12 | M10 | 32 | 125 | 15 | 29 |
| 06360-1214X80 | stainless steel | A | 14 | M12 | 36 | 80 | 16 | 33 |
| 06360-1214X100 | stainless steel | A | 14 | M12 | 36 | 100 | 16 | 33 |
| 06360-1214X125 | stainless steel | A | 14 | M12 | 36 | 125 | 16 | 33 |
| 06360-1214X160 | stainless steel | A | 14 | M12 | 36 | 160 | 16 | 33 |
| 06360-708X35 | steel | B | 8 | M6 | 23 | 35 | 9 | 60 |
| 06360-708X50 | steel | B | 8 | M6 | 23 | 50 | 9 | 60 |
| 06360-708X65 | steel | B | 8 | M6 | 23 | 65 | 9 | 60 |
| 06360-710X50 | steel | B | 10 | M8 | 26 | 50 | 13 | 70 |
| 06360-710X65 | steel | B | 10 | M8 | 26 | 65 | 13 | 70 |
| 06360-710X80 | steel | B | 10 | M8 | 26 | 80 | 13 | 70 |
| 06360-710X100 | steel | B | 10 | M8 | 26 | 100 | 13 | 70 |
| 06360-712X65 | steel | B | 12 | M10 | 35 | 65 | 15 | 85 |
| 06360-712X80 | steel | B | 12 | M10 | 35 | 80 | 15 | 85 |
| 06360-712X100 | steel | B | 12 | M10 | 35 | 100 | 15 | 85 |
| 06360-712X125 | steel | B | 12 | M10 | 35 | 125 | 15 | 85 |
| 06360-714X80 | steel | B | 14 | M12 | 35 | 80 | 16 | 85 |
| 06360-714X100 | steel | B | 14 | M12 | 35 | 100 | 16 | 85 |
| 06360-714X125 | steel | B | 14 | M12 | 35 | 125 | 16 | 85 |
| 06360-714X160 | steel | B | 14 | M12 | 35 | 160 | 16 | 85 |
| 06360-1708X35 | stainless steel | B | 8 | M6 | 23 | 35 | 9 | 60 |
| 06360-1708X50 | stainless steel | B | 8 | M6 | 23 | 50 | 9 | 60 |
| 06360-1708X65 | stainless steel | B | 8 | M6 | 23 | 65 | 9 | 60 |
| 06360-1710X50 | stainless steel | B | 10 | M8 | 26 | 50 | 13 | 70 |
| 06360-1710X65 | stainless steel | B | 10 | M8 | 26 | 65 | 13 | 70 |
| 06360-1710X80 | stainless steel | B | 10 | M8 | 26 | 80 | 13 | 70 |
| 06360-1710X100 | stainless steel | B | 10 | M8 | 26 | 100 | 13 | 70 |
| 06360-1712X65 | stainless steel | B | 12 | M10 | 35 | 65 | 15 | 85 |
| 06360-1712X80 | stainless steel | B | 12 | M10 | 35 | 80 | 15 | 85 |
| 06360-1712X100 | stainless steel | B | 12 | M10 | 35 | 100 | 15 | 85 |
| 06360-1712X125 | stainless steel | B | 12 | M10 | 35 | 125 | 15 | 85 |
| 06360-1714X80 | stainless steel | B | 14 | M12 | 35 | 80 | 16 | 85 |
| 06360-1714X100 | stainless steel | B | 14 | M12 | 35 | 100 | 16 | 85 |
| 06360-1714X125 | stainless steel | B | 14 | M12 | 35 | 125 | 16 | 85 |
| 06360-1714X160 | stainless steel | B | 14 | M12 | 35 | 160 | 16 | 85 |
| 06360-408X35 | steel | C | 8 | M6 | 20 | 35 | 9 | 31 |
| 06360-408X50 | steel | C | 8 | M6 | 20 | 50 | 9 | 31 |
| 06360-408X65 | steel | C | 8 | M6 | 20 | 65 | 9 | 31 |
| 06360-410X50 | steel | C | 10 | M8 | 25 | 50 | 13 | 38 |
| 06360-410X65 | steel | C | 10 | M8 | 25 | 65 | 13 | 38 |
| 06360-410X80 | steel | C | 10 | M8 | 25 | 80 | 13 | 38 |
| 06360-410X100 | steel | C | 10 | M8 | 25 | 100 | 13 | 38 |
| 06360-412X65 | steel | C | 12 | M10 | 30 | 65 | 15 | 46 |
| 06360-412X80 | steel | C | 12 | M10 | 30 | 80 | 15 | 46 |
| 06360-412X100 | steel | C | 12 | M10 | 30 | 100 | 15 | 46 |
| 06360-412X125 | steel | C | 12 | M10 | 30 | 125 | 15 | 46 |
| 06360-414X80 | steel | C | 14 | M12 | 35 | 80 | 16 | 53 |
| 06360-414X100 | steel | C | 14 | M12 | 35 | 100 | 16 | 53 |
| 06360-414X125 | steel | C | 14 | M12 | 35 | 125 | 16 | 53 |
| 06360-414X160 | steel | C | 14 | M12 | 35 | 160 | 16 | 53 |
| 06360-1408X35 | stainless steel | C | 8 | M6 | 20 | 35 | 9 | 31 |
| 06360-1408X50 | stainless steel | C | 8 | M6 | 20 | 50 | 9 | 31 |
| 06360-1408X65 | stainless steel | C | 8 | M6 | 20 | 65 | 9 | 31 |
| 06360-1410X50 | stainless steel | C | 10 | M8 | 25 | 50 | 13 | 38 |
| 06360-1410X65 | stainless steel | C | 10 | M8 | 25 | 65 | 13 | 38 |
| 06360-1410X80 | stainless steel | C | 10 | M8 | 25 | 80 | 13 | 38 |
| 06360-1410X100 | stainless steel | C | 10 | M8 | 25 | 100 | 13 | 38 |
| 06360-1412X65 | stainless steel | C | 12 | M10 | 30 | 65 | 15 | 46 |
| 06360-1412X80 | stainless steel | C | 12 | M10 | 30 | 80 | 15 | 46 |
| 06360-1412X100 | stainless steel | C | 12 | M10 | 30 | 100 | 15 | 46 |
| 06360-1412X125 | stainless steel | C | 12 | M10 | 30 | 125 | 15 | 46 |
| 06360-1414X80 | stainless steel | C | 14 | M12 | 35 | 80 | 16 | 53 |
| 06360-1414X100 | stainless steel | C | 14 | M12 | 35 | 100 | 16 | 53 |

Overview of items

| Order No. | Main material | Form | D | D1 | D2 | L | L1 | L2 |
|----------------|-----------------|------|----|-----|----|-----|----|----|
| 06360-1414X125 | stainless steel | C | 14 | M12 | 35 | 125 | 16 | 53 |
| 06360-1414X160 | stainless steel | C | 14 | M12 | 35 | 160 | 16 | 53 |
| 06360-608X35 | steel | E | 8 | M6 | 17 | 35 | 9 | 45 |
| 06360-608X50 | steel | E | 8 | M6 | 17 | 50 | 9 | 45 |
| 06360-608X65 | steel | E | 8 | M6 | 17 | 65 | 9 | 45 |
| 06360-610X50 | steel | E | 10 | M8 | 23 | 50 | 13 | 61 |
| 06360-610X65 | steel | E | 10 | M8 | 23 | 65 | 13 | 61 |
| 06360-610X80 | steel | E | 10 | M8 | 23 | 80 | 13 | 61 |
| 06360-610X100 | steel | E | 10 | M8 | 23 | 100 | 13 | 61 |
| 06360-612X65 | steel | E | 12 | M10 | 29 | 65 | 15 | 71 |
| 06360-612X80 | steel | E | 12 | M10 | 29 | 80 | 15 | 71 |
| 06360-612X100 | steel | E | 12 | M10 | 29 | 100 | 15 | 71 |
| 06360-612X125 | steel | E | 12 | M10 | 29 | 125 | 15 | 71 |
| 06360-614X80 | steel | E | 14 | M12 | 29 | 80 | 16 | 71 |
| 06360-614X100 | steel | E | 14 | M12 | 29 | 100 | 16 | 71 |
| 06360-614X125 | steel | E | 14 | M12 | 29 | 125 | 16 | 71 |
| 06360-614X160 | steel | E | 14 | M12 | 29 | 160 | 16 | 71 |
| 06360-1608X35 | stainless steel | E | 8 | M6 | 17 | 35 | 9 | 45 |
| 06360-1608X50 | stainless steel | E | 8 | M6 | 17 | 50 | 9 | 45 |
| 06360-1608X65 | stainless steel | E | 8 | M6 | 17 | 65 | 9 | 45 |
| 06360-1610X50 | stainless steel | E | 10 | M8 | 23 | 50 | 13 | 61 |
| 06360-1610X65 | stainless steel | E | 10 | M8 | 23 | 65 | 13 | 61 |
| 06360-1610X80 | stainless steel | E | 10 | M8 | 23 | 80 | 13 | 61 |
| 06360-1610X100 | stainless steel | E | 10 | M8 | 23 | 100 | 13 | 61 |
| 06360-1612X65 | stainless steel | E | 12 | M10 | 29 | 65 | 15 | 71 |
| 06360-1612X80 | stainless steel | E | 12 | M10 | 29 | 80 | 15 | 71 |
| 06360-1612X100 | stainless steel | E | 12 | M10 | 29 | 100 | 15 | 71 |
| 06360-1612X125 | stainless steel | E | 12 | M10 | 29 | 125 | 15 | 71 |
| 06360-1614X80 | stainless steel | E | 14 | M12 | 29 | 80 | 16 | 71 |
| 06360-1614X100 | stainless steel | E | 14 | M12 | 29 | 100 | 16 | 71 |
| 06360-1614X125 | stainless steel | E | 14 | M12 | 29 | 125 | 16 | 71 |
| 06360-1614X160 | stainless steel | E | 14 | M12 | 29 | 160 | 16 | 71 |