



lift to  
disengage



### Description

**Material:**

Handle die-cast zinc DIN EN 12844.  
Steel parts grade 5.8.

**Version:**

Handle powder-coated.  
Steel parts black oxidised.

**Note:**

Standard colours are:  
orange RAL 2004.

Where L is  $\geq 60$  mm the thread length is 60 mm.


**On request:**

Other threads, screw lengths, colours and special versions.  
Dimension "H1" available in other lengths at extra charge.

**Drawing reference:**

1) flat point DIN EN ISO 4753

### Drawings

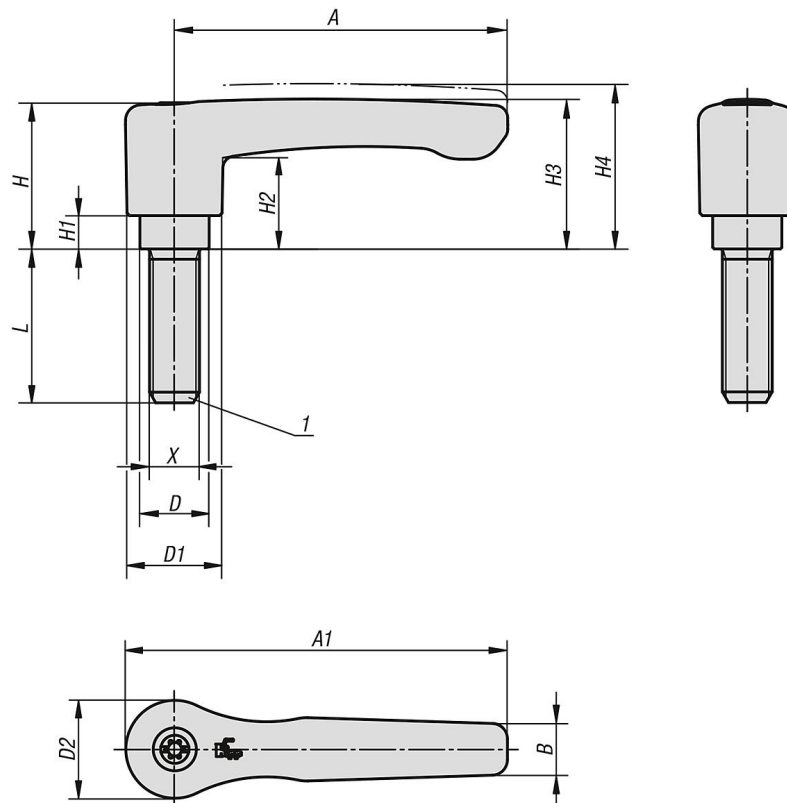

# 06458 Clamping levers, die-cast zinc, flat with external thread, threaded pin black oxidised steel



## Overview of items

Order No.	Main colour	Surface finish body	Size	X	D	D1	D2	H	H1	H2	H3	H4	A	A1	B	No. of teeth	L
06458-2062X15	orange RAL 2004	plastic-coated	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	15
06458-2062X20	orange RAL 2004	plastic-coated	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	20
06458-2062X25	orange RAL 2004	plastic-coated	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	25
06458-2062X30	orange RAL 2004	plastic-coated	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	30
06458-2062X35	orange RAL 2004	plastic-coated	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	35
06458-2062X40	orange RAL 2004	plastic-coated	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	40
06458-2062X45	orange RAL 2004	plastic-coated	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	45
06458-2062X50	orange RAL 2004	plastic-coated	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	50
06458-2062X55	orange RAL 2004	plastic-coated	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	55
06458-2062X60	orange RAL 2004	plastic-coated	2	M6	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	60
06458-2082X15	orange RAL 2004	plastic-coated	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	15
06458-2082X20	orange RAL 2004	plastic-coated	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	20
06458-2082X25	orange RAL 2004	plastic-coated	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	25
06458-2082X30	orange RAL 2004	plastic-coated	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	30
06458-2082X35	orange RAL 2004	plastic-coated	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	35
06458-2082X40	orange RAL 2004	plastic-coated	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	40
06458-2082X45	orange RAL 2004	plastic-coated	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	45
06458-2082X50	orange RAL 2004	plastic-coated	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	50
06458-2082X55	orange RAL 2004	plastic-coated	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	55
06458-2082X60	orange RAL 2004	plastic-coated	2	M8	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	60
06458-2102X15	orange RAL 2004	plastic-coated	2	M10	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	15
06458-2102X20	orange RAL 2004	plastic-coated	2	M10	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	20
06458-2102X25	orange RAL 2004	plastic-coated	2	M10	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	25
06458-2102X30	orange RAL 2004	plastic-coated	2	M10	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	30
06458-2102X35	orange RAL 2004	plastic-coated	2	M10	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	35
06458-2102X40	orange RAL 2004	plastic-coated	2	M10	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	40
06458-2102X45	orange RAL 2004	plastic-coated	2	M10	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	45
06458-2102X50	orange RAL 2004	plastic-coated	2	M10	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	50
06458-2102X55	orange RAL 2004	plastic-coated	2	M10	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	55
06458-2102X60	orange RAL 2004	plastic-coated	2	M10	13,5	18,5	19,1	28,5	6,5	17,8	29,2	32,2	65	74,5	10,1	20	60
06458-3082X15	orange RAL 2004	plastic-coated	3	M8	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	15
06458-3082X20	orange RAL 2004	plastic-coated	3	M8	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	20
06458-3082X25	orange RAL 2004	plastic-coated	3	M8	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	25
06458-3082X30	orange RAL 2004	plastic-coated	3	M8	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	30
06458-3082X35	orange RAL 2004	plastic-coated	3	M8	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	35
06458-3082X40	orange RAL 2004	plastic-coated	3	M8	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	40
06458-3082X45	orange RAL 2004	plastic-coated	3	M8	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	45
06458-3082X50	orange RAL 2004	plastic-coated	3	M8	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	50
06458-3082X55	orange RAL 2004	plastic-coated	3	M8	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	55
06458-3082X60	orange RAL 2004	plastic-coated	3	M8	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	60
06458-3102X15	orange RAL 2004	plastic-coated	3	M10	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	15
06458-3102X20	orange RAL 2004	plastic-coated	3	M10	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	20
06458-3102X25	orange RAL 2004	plastic-coated	3	M10	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	25
06458-3102X30	orange RAL 2004	plastic-coated	3	M10	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	30
06458-3102X35	orange RAL 2004	plastic-coated	3	M10	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	35
06458-3102X40	orange RAL 2004	plastic-coated	3	M10	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	40
06458-3102X45	orange RAL 2004	plastic-coated	3	M10	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	45
06458-3102X50	orange RAL 2004	plastic-coated	3	M10	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	50
06458-3102X55	orange RAL 2004	plastic-coated	3	M10	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	55
06458-3102X60	orange RAL 2004	plastic-coated	3	M10	16	21,2	22	37	10	23,8	38	42	80	91	11,7	22	60