

Item description/product images

**Description****Material:**

Centring flange QT steel 1.1191 or 1.1192.


Note:

The centring flange with bore is a high-quality component that can be used in tool and die making. This centring flange has a precise shoulder that facilitates easy alignment and positioning of tools or dies. The conical bore of the flange provides excellent guidance and ensures a secure connection between different parts.


The centring flange with shoulder is an outstanding choice for tool and die making applications that require precise alignment. This flange has a shoulder that facilitates the alignment of parts and ensures stable positioning.

The centring flange with shoulder and screw holes can be used in tool and die making where precise alignment, secure fastening and reliable positioning are essential. Its combination of precise functions and screw holes makes it highly versatile in various manufacturing applications.



(A)

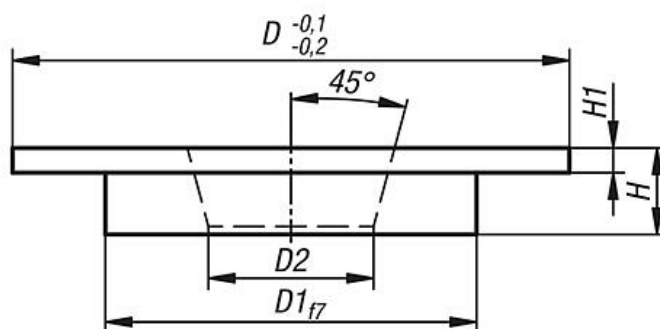

(B)

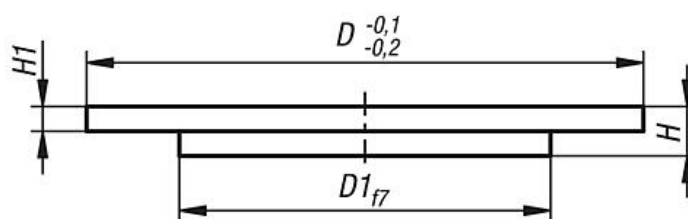

(C)

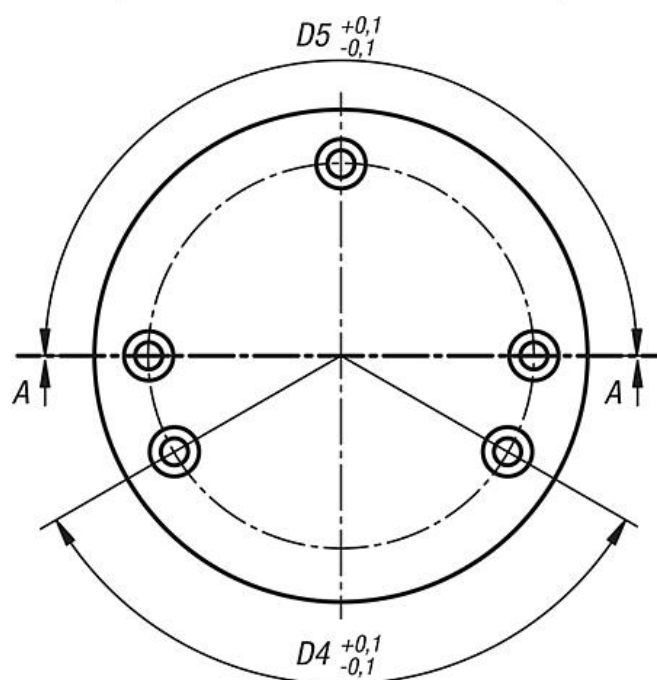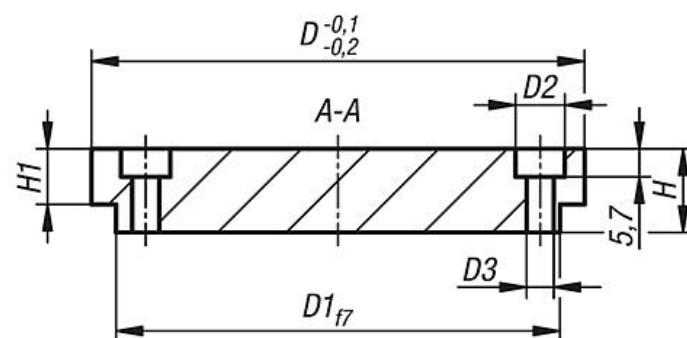

Overview of items

Order No.	Form	Form definition	Steel code	D	D1	D2	D3	D4	D5	H	H1
03152-30-006008	A	deep groove ball bearings	1.1191	90	60	36	-	-	-	8	4
03152-30-006011	A	deep groove ball bearings	1.1191	90	60	26	-	-	-	11	4
03152-30-006013	A	deep groove ball bearings	1.1191	90	60	26	-	-	-	13	4
03152-30-006014	A	deep groove ball bearings	1.1191	90	60	26	-	-	-	14	4
03152-30-008012	A	deep groove ball bearings	1.1191	90	80	36	-	-	-	12	8
03152-30-008015	A	deep groove ball bearings	1.1191	90	80	26	-	-	-	15	8
03152-30-008017	A	deep groove ball bearings	1.1191	90	80	26	-	-	-	17	8
03152-30-009012	A	deep groove ball bearings	1.1191	90	90	36	-	-	-	12	8
03152-30-009015	A	deep groove ball bearings	1.1191	90	90	36	-	-	-	15	8
03152-30-009017	A	deep groove ball bearings	1.1191	90	90	36	-	-	-	17	8
03152-30-009018	A	deep groove ball bearings	1.1191	90	90	36	-	-	-	18	8
03152-30-009019	A	deep groove ball bearings	1.1191	90	90	36	-	-	-	19	8
03152-30-009021	A	deep groove ball bearings	1.1191	90	90	36	-	-	-	21	8,5
03152-30-010012	A	deep groove ball bearings	1.1191	100	90	36	-	-	-	12	8
03152-30-010015	A	deep groove ball bearings	1.1191	100	90	36	-	-	-	15	8
03152-30-010017	A	deep groove ball bearings	1.1191	100	90	36	-	-	-	17	8
03152-30-010019	A	deep groove ball bearings	1.1191	100	90	36	-	-	-	19	8
03152-30-010021	A	deep groove ball bearings	1.1191	100	90	36	-	-	-	21	8,5
03152-30-011012	A	deep groove ball bearings	1.1191	110	90	36	-	-	-	12	8
03152-30-011015	A	deep groove ball bearings	1.1191	110	90	36	-	-	-	15	8
03152-30-011017	A	deep groove ball bearings	1.1191	110	90	36	-	-	-	17	8
03152-30-011018	A	deep groove ball bearings	1.1191	110	90	36	-	-	-	18	8
03152-30-011019	A	deep groove ball bearings	1.1191	110	90	36	-	-	-	19	8
03152-30-011020	A	deep groove ball bearings	1.1191	110	90	36	-	-	-	20	8
03152-30-011021	A	deep groove ball bearings	1.1191	110	90	36	-	-	-	21	8,5
03152-30-012012	A	deep groove ball bearings	1.1191	120	90	36	-	-	-	12	8
03152-30-012015	A	deep groove ball bearings	1.1191	120	90	36	-	-	-	15	8
03152-30-012017	A	deep groove ball bearings	1.1191	120	90	36	-	-	-	17	8
03152-30-012018	A	deep groove ball bearings	1.1191	120	90	36	-	-	-	18	8
03152-30-012019	A	deep groove ball bearings	1.1191	120	90	36	-	-	-	19	8
03152-30-012020	A	deep groove ball bearings	1.1191	120	90	36	-	-	-	20	8
03152-30-012021	A	deep groove ball bearings	1.1191	120	90	36	-	-	-	21	8,5
03152-30-012512	A	deep groove ball bearings	1.1191	125	90	36	-	-	-	12	8
03152-30-012515	A	deep groove ball bearings	1.1191	125	90	36	-	-	-	15	8
03152-30-012517	A	deep groove ball bearings	1.1191	125	90	36	-	-	-	17	8
03152-30-012518	A	deep groove ball bearings	1.1191	125	90	36	-	-	-	18	8
03152-30-012519	A	deep groove ball bearings	1.1191	125	90	36	-	-	-	19	8
03152-30-012520	A	deep groove ball bearings	1.1191	125	90	36	-	-	-	20	8
03152-30-012521	A	deep groove ball bearings	1.1191	125	90	36	-	-	-	21	8,5
03152-30-013012	A	deep groove ball bearings	1.1191	130	90	36	-	-	-	12	8
03152-30-014012	A	deep groove ball bearings	1.1191	140	90	36	-	-	-	12	8
03152-30-015012	A	deep groove ball bearings	1.1191	150	90	36	-	-	-	12	8
03152-30-016012	A	deep groove ball bearings	1.1191	160	90	36	-	-	-	12	8
03152-30-016015	A	deep groove ball bearings	1.1191	160	90	36	-	-	-	15	8
03152-30-016017	A	deep groove ball bearings	1.1191	160	90	36	-	-	-	17	8
03152-30-016018	A	deep groove ball bearings	1.1191	160	90	36	-	-	-	18	8
03152-30-016019	A	deep groove ball bearings	1.1191	160	90	36	-	-	-	19	8
03152-30-016020	A	deep groove ball bearings	1.1191	160	90	36	-	-	-	20	8
03152-30-016021	A	deep groove ball bearings	1.1191	160	90	36	-	-	-	21	8,5
03152-30-017512	A	deep groove ball bearings	1.1191	175	90	36	-	-	-	12	8
03152-30-017515	A	deep groove ball bearings	1.1191	175	90	36	-	-	-	15	8
03152-30-017517	A	deep groove ball bearings	1.1191	175	90	36	-	-	-	17	8
03152-30-017518	A	deep groove ball bearings	1.1191	175	90	36	-	-	-	18	8
03152-30-017519	A	deep groove ball bearings	1.1191	175	90	36	-	-	-	19	8
03152-30-017520	A	deep groove ball bearings	1.1191	175	90	36	-	-	-	20	8
03152-30-017521	A	deep groove ball bearings	1.1191	175	90	36	-	-	-	21	8,5
03152-30-018012	A	deep groove ball bearings	1.1191	180	90	36	-	-	-	12	8
03152-30-020012	A	deep groove ball bearings	1.1191	200	90	36	-	-	-	12	8
03152-30-025012	A	deep groove ball bearings	1.1191	250	90	36	-	-	-	12	8
03152-30-106008	B	Dial gauge holder with hydraulic lock	1.1191	90	60	-	-	-	-	8	4
03152-30-106011	B	Dial gauge holder with hydraulic lock	1.1191	90	60	-	-	-	-	11	4
03152-30-106013	B	Dial gauge holder with hydraulic lock	1.1191	90	60	-	-	-	-	13	4
03152-30-106014	B	Dial gauge holder with hydraulic lock	1.1191	90	60	-	-	-	-	14	4
03152-30-108012	B	Dial gauge holder with hydraulic lock	1.1191	90	80	-	-	-	-	12	8
03152-30-108015	B	Dial gauge holder with hydraulic lock	1.1191	90	80	-	-	-	-	15	8

Overview of items

Order No.	Form	Form definition	Steel code	D	D1	D2	D3	D4	D5	H	H1
03152-30-108017	B	Dial gauge holder with hydraulic lock	1.1191	90	80	-	-	-	-	17	8
03152-30-110012	B	Dial gauge holder with hydraulic lock	1.1191	100	90	-	-	-	-	12	8
03152-30-110015	B	Dial gauge holder with hydraulic lock	1.1191	100	90	-	-	-	-	15	8
03152-30-110017	B	Dial gauge holder with hydraulic lock	1.1191	100	90	-	-	-	-	17	8
03152-30-110018	B	Dial gauge holder with hydraulic lock	1.1191	100	90	-	-	-	-	18	8
03152-30-110019	B	Dial gauge holder with hydraulic lock	1.1191	100	90	-	-	-	-	19	8
03152-30-110021	B	Dial gauge holder with hydraulic lock	1.1191	100	90	-	-	-	-	21	8,5
03152-30-111012	B	Dial gauge holder with hydraulic lock	1.1191	110	90	-	-	-	-	12	8
03152-30-111015	B	Dial gauge holder with hydraulic lock	1.1191	110	90	-	-	-	-	15	8
03152-30-111017	B	Dial gauge holder with hydraulic lock	1.1191	110	90	-	-	-	-	17	8
03152-30-111018	B	Dial gauge holder with hydraulic lock	1.1191	110	90	-	-	-	-	18	8
03152-30-111019	B	Dial gauge holder with hydraulic lock	1.1191	110	90	-	-	-	-	19	8
03152-30-111020	B	Dial gauge holder with hydraulic lock	1.1191	110	90	-	-	-	-	20	8
03152-30-111021	B	Dial gauge holder with hydraulic lock	1.1191	110	90	-	-	-	-	21	8,5
03152-30-112012	B	Dial gauge holder with hydraulic lock	1.1191	120	90	-	-	-	-	12	8
03152-30-112015	B	Dial gauge holder with hydraulic lock	1.1191	120	90	-	-	-	-	15	8
03152-30-112017	B	Dial gauge holder with hydraulic lock	1.1191	120	90	-	-	-	-	17	8
03152-30-112018	B	Dial gauge holder with hydraulic lock	1.1191	120	90	-	-	-	-	18	8
03152-30-112019	B	Dial gauge holder with hydraulic lock	1.1191	120	90	-	-	-	-	19	8
03152-30-112020	B	Dial gauge holder with hydraulic lock	1.1191	120	90	-	-	-	-	20	8
03152-30-112021	B	Dial gauge holder with hydraulic lock	1.1191	120	90	-	-	-	-	21	8,5
03152-30-112512	B	Dial gauge holder with hydraulic lock	1.1191	125	90	-	-	-	-	12	8
03152-30-112515	B	Dial gauge holder with hydraulic lock	1.1191	125	90	-	-	-	-	15	8
03152-30-112517	B	Dial gauge holder with hydraulic lock	1.1191	125	90	-	-	-	-	17	8
03152-30-112518	B	Dial gauge holder with hydraulic lock	1.1191	125	90	-	-	-	-	18	8
03152-30-112519	B	Dial gauge holder with hydraulic lock	1.1191	125	90	-	-	-	-	19	8
03152-30-112520	B	Dial gauge holder with hydraulic lock	1.1191	125	90	-	-	-	-	20	8
03152-30-112521	B	Dial gauge holder with hydraulic lock	1.1191	125	90	-	-	-	-	21	8,5
03152-30-114012	B	Dial gauge holder with hydraulic lock	1.1191	140	90	-	-	-	-	12	8
03152-30-115012	B	Dial gauge holder with hydraulic lock	1.1191	150	90	-	-	-	-	12	8
03152-30-116012	B	Dial gauge holder with hydraulic lock	1.1191	160	90	-	-	-	-	12	8
03152-30-116015	B	Dial gauge holder with hydraulic lock	1.1191	160	90	-	-	-	-	15	8
03152-30-116017	B	Dial gauge holder with hydraulic lock	1.1191	160	90	-	-	-	-	17	8
03152-30-116018	B	Dial gauge holder with hydraulic lock	1.1191	160	90	-	-	-	-	18	8
03152-30-116019	B	Dial gauge holder with hydraulic lock	1.1191	160	90	-	-	-	-	19	8
03152-30-116020	B	Dial gauge holder with hydraulic lock	1.1191	160	90	-	-	-	-	20	8
03152-30-116021	B	Dial gauge holder with hydraulic lock	1.1191	160	90	-	-	-	-	21	8,5
03152-30-117512	B	Dial gauge holder with hydraulic lock	1.1191	175	90	-	-	-	-	12	8
03152-30-117515	B	Dial gauge holder with hydraulic lock	1.1191	175	90	-	-	-	-	15	8
03152-30-117517	B	Dial gauge holder with hydraulic lock	1.1191	175	90	-	-	-	-	17	8
03152-30-117518	B	Dial gauge holder with hydraulic lock	1.1191	175	90	-	-	-	-	18	8
03152-30-117519	B	Dial gauge holder with hydraulic lock	1.1191	175	90	-	-	-	-	19	8
03152-30-117520	B	Dial gauge holder with hydraulic lock	1.1191	175	90	-	-	-	-	20	8
03152-30-117521	B	Dial gauge holder with hydraulic lock	1.1191	175	90	-	-	-	-	21	8,5
03152-30-120012	B	Dial gauge holder with hydraulic lock	1.1191	200	90	-	-	-	-	12	8
03152-30-125012	B	Dial gauge holder with hydraulic lock	1.1191	250	90	-	-	-	-	12	8
03152-30-210017	C	silver	1.1192	100	90	10	5,5	78	82	17	8
03152-30-211019	C	silver	1.1192	110	90	10	5,5	78	98	19	8
03152-30-212512	C	silver	1.1192	125	90	10	5,5	78	104	12	8
03152-30-212517	C	silver	1.1192	125	90	10	5,5	78	104	17	8
03152-30-212519	C	silver	1.1192	125	90	10	5,5	78	104	19	8
03152-30-212521	C	silver	1.1192	125	90	10	5,5	78	104	21	8
03152-30-216021	C	silver	1.1192	160	90	10	5,5	78	128	21	8