
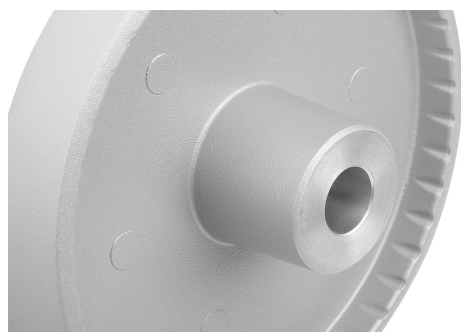


Item description/product images

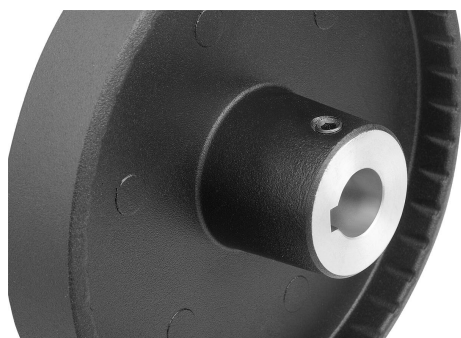

Description

Material:

Handwheel aluminium.

Hub cover black thermoplastic.

ISO 4027 grub screw, steel grade 45 H, black.

Version:

Black or silver powder-coated.

With reamed hole.

With reamed hole and keyway.

With reamed hole and transverse bore.

With reamed hole, keyway and transverse bore.

Note:

Wheel rim radial and axial run-out ≤ 0.4 mm.

Assembly:

The hub cover is supplied unassembled.

The handwheels can be secured to a shaft using a transverse pin or by parallel key connection together with a DIN 6912 cap screw and a handwheel washer 07375.

By the versions with transverse bore, fixation is carried out using an ISO 4027 grub screw.

Supplied with:

Aluminium handwheel.

Hub cover.

ISO 4027 grub screw (type with transverse bore).

Accessory:


07375 Handwheel washers.

07161 Socket head screws with low head DIN 6912.


Drawing reference:

1) Position of the transverse bore to the keyway is offset by 90° .

Item description/product images

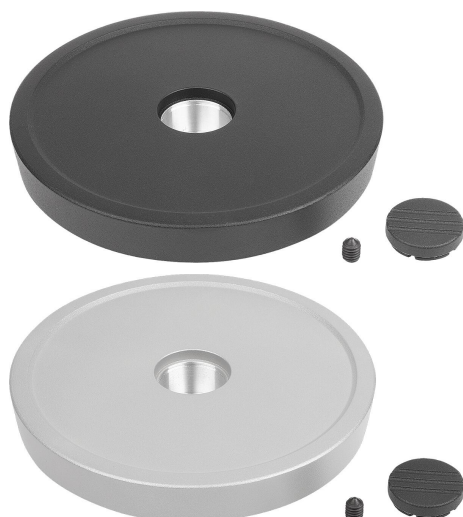

Drawings

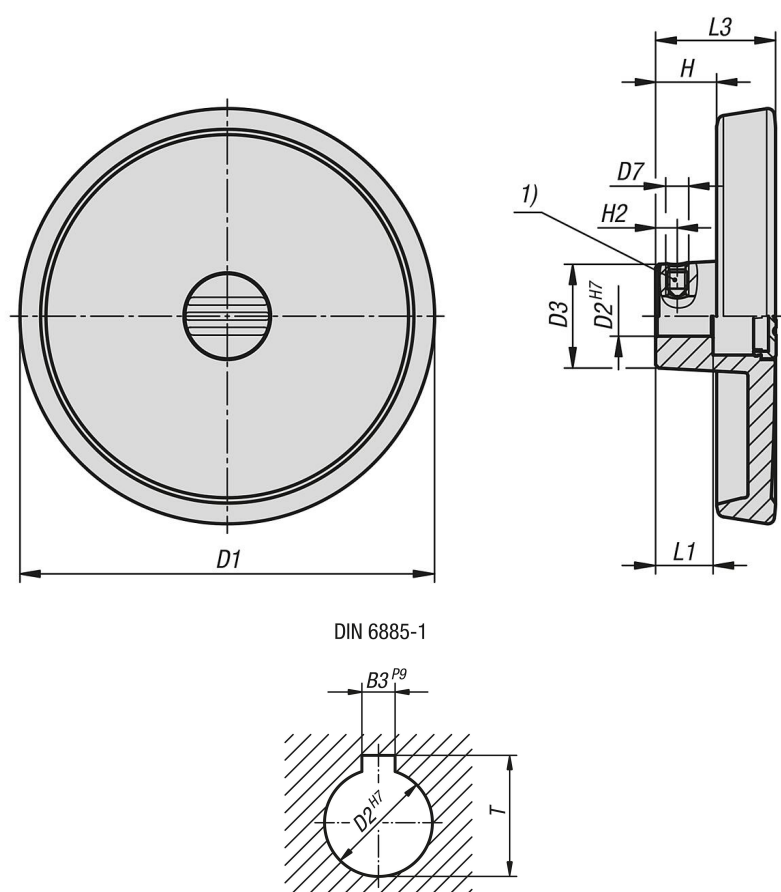

Overview of items

Order No.	Main colour	Form	Form definition	D1	D2	D3	L1	L3	H	H2	D7	B3	T
06278-0801016	9-pin	A	precipitation hardened	80	10	26	16	29	16,6	5,5	M6	-	-
06278-0801216	9-pin	A	precipitation hardened	80	12	26	16	29	16,6	6,5	M6	-	-
06278-1001016	9-pin	A	precipitation hardened	100	10	28	17	33	17,5	5,5	M6	-	-
06278-1001216	9-pin	A	precipitation hardened	100	12	28	17	33	17,5	6,5	M6	-	-

Overview of items

Order No.	Main colour	Form	Form definition	D1	D2	D3	L1	L3	H	H2	D7	B3	T
06278-1251216	9-pin	A	precipitation hardened	125	12	31	18	36	18,3	6,5	M6	-	-
06278-1251416	9-pin	A	precipitation hardened	125	14	31	18	36	18,3	6,5	M6	-	-
06278-0801026	Bushing and fitting pieces	A	precipitation hardened	80	10	26	16	29	16,6	5,5	M6	-	-
06278-0801226	Bushing and fitting pieces	A	precipitation hardened	80	12	26	16	29	16,6	6,5	M6	-	-
06278-1001026	Bushing and fitting pieces	A	precipitation hardened	100	10	28	17	33	17,5	5,5	M6	-	-
06278-1001226	Bushing and fitting pieces	A	precipitation hardened	100	12	28	17	33	17,5	6,5	M6	-	-
06278-1251226	Bushing and fitting pieces	A	precipitation hardened	125	12	31	18	36	18,3	6,5	M6	-	-
06278-1251426	Bushing and fitting pieces	A	precipitation hardened	125	14	31	18	36	18,3	6,5	M6	-	-
06278-080101036	9-pin	B	Protective Insert	80	10	26	16	29	16,6	5,5	M6	3	11,4
06278-080121046	9-pin	B	Protective Insert	80	12	26	16	29	16,6	6,5	M6	4	13,8
06278-100101036	9-pin	B	Protective Insert	100	10	28	17	33	17,5	5,5	M6	3	11,4
06278-100121046	9-pin	B	Protective Insert	100	12	28	17	33	17,5	6,5	M6	4	13,8
06278-125121046	9-pin	B	Protective Insert	125	12	31	18	36	18,3	6,5	M6	4	13,8
06278-125141056	9-pin	B	Protective Insert	125	14	31	18	36	18,3	6,5	M6	5	16,3
06278-080102036	Bushing and fitting pieces	B	Protective Insert	80	10	26	16	29	16,6	5,5	M6	3	11,4
06278-080122046	Bushing and fitting pieces	B	Protective Insert	80	12	26	16	29	16,6	6,5	M6	4	13,8
06278-100102036	Bushing and fitting pieces	B	Protective Insert	100	10	28	17	33	17,5	5,5	M6	3	11,4
06278-100122046	Bushing and fitting pieces	B	Protective Insert	100	12	28	17	33	17,5	6,5	M6	4	13,8
06278-125122046	Bushing and fitting pieces	B	Protective Insert	125	12	31	18	36	18,3	6,5	M6	4	13,8
06278-125142056	Bushing and fitting pieces	B	Protective Insert	125	14	31	18	36	18,3	6,5	M6	5	16,3
06278-08010103	9-pin	C	1 kg can	80	10	26	16	29	16,6	-	-	3	11,4
06278-08012104	9-pin	C	1 kg can	80	12	26	16	29	16,6	-	-	4	13,8
06278-10010103	9-pin	C	1 kg can	100	10	28	17	33	17,5	-	-	3	11,4
06278-10012104	9-pin	C	1 kg can	100	12	28	17	33	17,5	-	-	4	13,8
06278-12512104	9-pin	C	1 kg can	125	12	31	18	36	18,3	-	-	4	13,8
06278-12514105	9-pin	C	1 kg can	125	14	31	18	36	18,3	-	-	5	16,3
06278-08010203	Bushing and fitting pieces	C	1 kg can	80	10	26	16	29	16,6	-	-	3	11,4
06278-08012204	Bushing and fitting pieces	C	1 kg can	80	12	26	16	29	16,6	-	-	4	13,8
06278-10010203	Bushing and fitting pieces	C	1 kg can	100	10	28	17	33	17,5	-	-	3	11,4
06278-10012204	Bushing and fitting pieces	C	1 kg can	100	12	28	17	33	17,5	-	-	4	13,8
06278-12512204	Bushing and fitting pieces	C	1 kg can	125	12	31	18	36	18,3	-	-	4	13,8
06278-12514205	Bushing and fitting pieces	C	1 kg can	125	14	31	18	36	18,3	-	-	5	16,3
06278-080101	9-pin	E	Positioning table with fine adjustment	80	10	26	16	29	16,6	-	-	-	-
06278-080121	9-pin	E	Positioning table with fine adjustment	80	12	26	16	29	16,6	-	-	-	-
06278-100101	9-pin	E	Positioning table with fine adjustment	100	10	28	17	33	17,5	-	-	-	-
06278-100121	9-pin	E	Positioning table with fine adjustment	100	12	28	17	33	17,5	-	-	-	-
06278-125121	9-pin	E	Positioning table with fine adjustment	125	12	31	18	36	18,3	-	-	-	-
06278-125141	9-pin	E	Positioning table with fine adjustment	125	14	31	18	36	18,3	-	-	-	-
06278-080102	Bushing and fitting pieces	E	Positioning table with fine adjustment	80	10	26	16	29	16,6	-	-	-	-
06278-080122	Bushing and fitting pieces	E	Positioning table with fine adjustment	80	12	26	16	29	16,6	-	-	-	-
06278-100102	Bushing and fitting pieces	E	Positioning table with fine adjustment	100	10	28	17	33	17,5	-	-	-	-
06278-100122	Bushing and fitting pieces	E	Positioning table with fine adjustment	100	12	28	17	33	17,5	-	-	-	-
06278-125122	Bushing and fitting pieces	E	Positioning table with fine adjustment	125	12	31	18	36	18,3	-	-	-	-
06278-125142	Bushing and fitting pieces	E	Positioning table with fine adjustment	125	14	31	18	36	18,3	-	-	-	-