

Item description/product images



by MARTIN

Levelling Components

Description

Material:

Foot plate and threaded spindle stainless steel 1.4301.
Rubber base (NBR) Shore 85 +/-5, FDA tested.
Rubber seal, silicone, FDA tested.

Version:

Foot plate, high-gloss polished.
Threaded spindle, bright.
Rubber base, black.
Rubber seal, blue.

Note:

Certified according to 3-A Sanitary Standard.

The high surface quality, the double sealing of the thread and the special seal on the machine foot's spindle joint prevent dirt from sticking and reduce cleaning times to a minimum.

The machine foot is supplied with the 3-A logo.

Application:


The machine foot is particularly suitable for machines, plants and appliances in the foodstuff industry, breweries, dairies, beverage and pharmaceutical industries.

Accessory:

Thread cover 27791-10.

Drawing reference:

1) Adjustment range

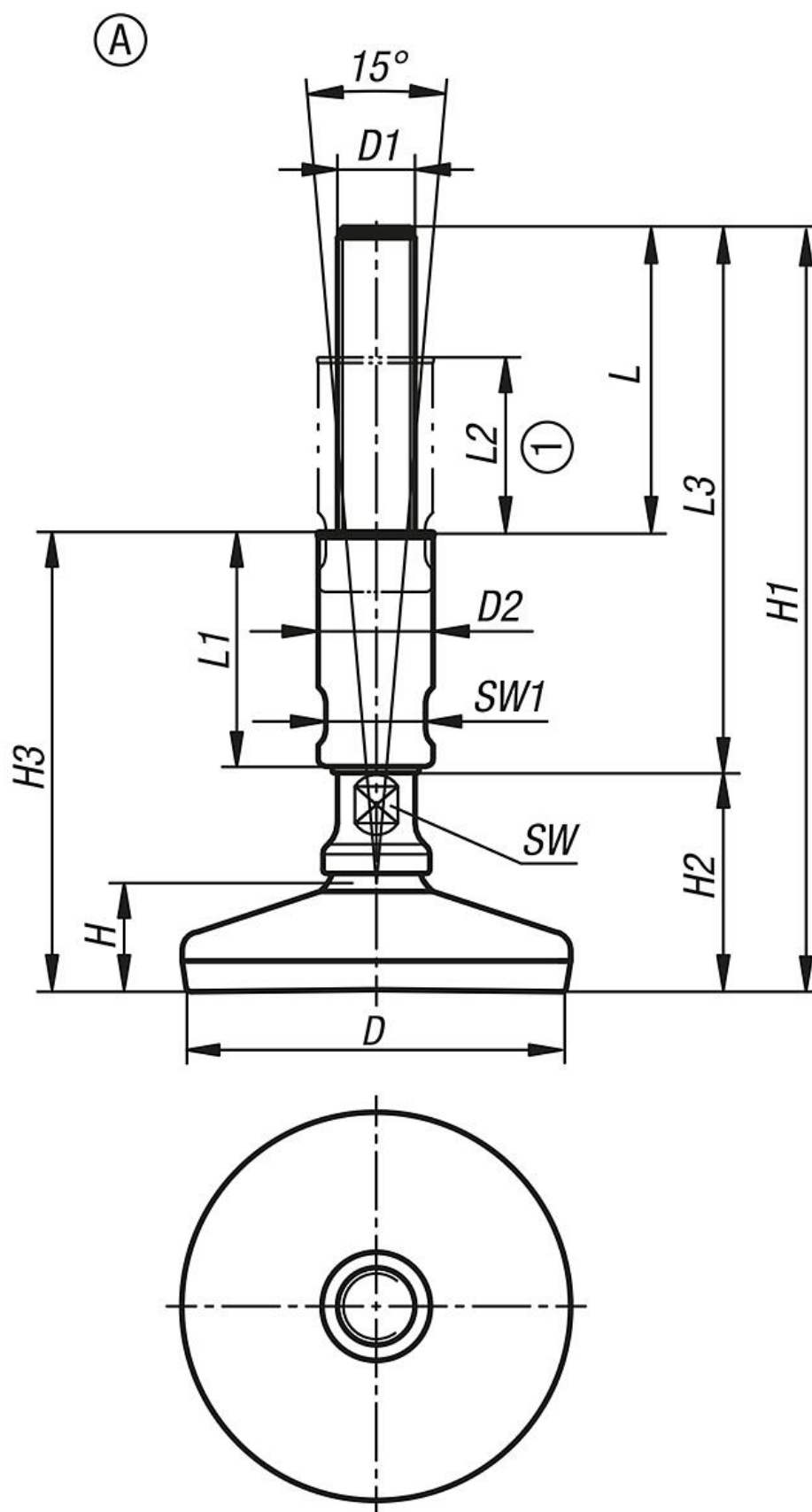

Overview of items

Order No.	Form	D	D1	D2	H	H1	H2	H3	L	L1	L2	L3	SW	SW	Load rating max. kN (static load only)
27791-05-1050A5X140	A	50	1/2-13	24	20	188	48	-	79	60	45	140	1/2	3/4	5
27791-05-1050A5X190	A	50	1/2-13	24	20	238	48	134	104	85	70	190	1/2	3/4	5
27791-05-1050A6X140	A	50	5/8-11	24	20	188	48	-	79	60	45	140	1/2	3/4	5
27791-05-1050A6X190	A	50	5/8-11	24	20	238	48	134	104	85	70	190	1/2	3/4	5
27791-05-1050A7X140	A	50	3/4-10	30	20	188	48	-	79	60	45	140	5/8	1	5
27791-05-1050A7X190	A	50	3/4-10	30	20	238	48	134	104	85	70	190	5/8	1	5
27791-05-1060A5X140	A	60	1/2-13	24	23	191	51	112	79	60	45	140	1/2	3/4	10
27791-05-1060A5X190	A	60	1/2-13	24	23	241	51	137	104	85	70	190	1/2	3/4	10
27791-05-1060A6X140	A	60	5/8-11	24	23	191	51	112	79	60	45	140	1/2	3/4	10
27791-05-1060A6X190	A	60	5/8-11	24	23	241	51	137	104	85	70	190	1/2	3/4	10
27791-05-1060A7X140	A	60	3/4-10	30	23	191	51	112	79	60	45	140	5/8	1	10
27791-05-1060A7X190	A	60	3/4-10	30	23	241	51	137	104	85	70	190	5/8	1	10
27791-05-1080A6X140	A	80	5/8-11	24	25	193	53	114	79	60	45	140	1/2	3/4	20
27791-05-1080A6X190	A	80	5/8-11	24	25	243	53	139	104	85	70	190	1/2	3/4	20
27791-05-1080A7X140	A	80	3/4-10	30	25	193	53	114	79	60	45	140	5/8	1	20
27791-05-1080A7X190	A	80	3/4-10	30	25	243	53	139	104	85	70	190	5/8	1	20
27791-05-1080A8X140	A	80	1-8	35	25	193	53	114	79	60	45	140	7/8	1,25	20
27791-05-1080A8X190	A	80	1-8	35	25	243	53	139	104	85	70	190	7/8	1,25	20
27791-05-1100A6X140	A	100	5/8-11	24	28	196	56	117	79	60	45	140	1/2	3/4	25
27791-05-1100A6X190	A	100	5/8-11	24	28	246	56	142	104	85	70	190	1/2	3/4	25
27791-05-1100A7X140	A	100	3/4-10	30	28	196	56	117	79	60	45	140	5/8	1	25
27791-05-1100A7X190	A	100	3/4-10	30	28	246	56	142	104	85	70	190	5/8	1	25
27791-05-1100A8X140	A	100	1-8	35	28	196	56	117	79	60	45	140	7/8	1,25	25
27791-05-1100A8X190	A	100	1-8	35	28	246	56	142	104	85	70	190	7/8	1,25	25
27791-05-1100AFX135	A	100	1 1/4-7	42	28	191	56	117	74	60	45	135	1,125	1,5	25
27791-05-1100AFX185	A	100	1 1/4-7	42	28	241	56	142	99	85	70	185	1,125	1,5	25
27791-05-1120A5X140	A	120	1/2-13	24	32	200	60	121	79	60	45	140	1/2	3/4	10
27791-05-1120A5X190	A	120	1/2-13	24	32	250	60	146	104	85	70	190	1/2	3/4	10
27791-05-1120A6X140	A	120	5/8-11	24	32	200	60	121	79	60	45	140	1/2	3/4	30
27791-05-1120A6X190	A	120	5/8-11	24	32	250	60	146	104	85	70	190	1/2	3/4	30
27791-05-1120A7X140	A	120	3/4-10	30	32	200	60	121	79	60	45	140	5/8	1	30
27791-05-1120A7X190	A	120	3/4-10	30	32	250	60	146	104	85	70	190	5/8	1	30
27791-05-1120A8X140	A	120	1-8	35	32	200	60	121	79	60	45	140	7/8	1,25	30
27791-05-1120A8X190	A	120	1-8	35	32	250	60	146	104	85	70	190	7/8	1,25	30
27791-05-1120AFX135	A	120	1 1/4-7	42	32	195	60	121	74	60	45	135	1,125	1,5	30
27791-05-1120AFX185	A	120	1 1/4-7	42	32	245	60	146	99	85	65	185	1,125	1,5	30
27791-05-1120AFX235	A	120	1 1/4-7	42	32	295	60	-	99	85	65	235	1,125	1,5	30
27791-05-1150A7X140	A	150	3/4-10	30	35	203	63	-	79	60	45	140	5/8	1	35
27791-05-1150A7X190	A	150	3/4-10	30	35	253	63	-	104	85	70	190	5/8	1	35
27791-05-1150A8X140	A	150	1-8	35	35	203	63	-	79	60	45	140	7/8	1,25	35
27791-05-1150A8X190	A	150	1-8	35	35	253	63	-	104	85	70	190	7/8	1,25	35
27791-05-1150AFX135	A	150	1 1/4-7	42	35	198	63	-	74	60	40	135	1,125	1,5	35
27791-05-1150AFX185	A	150	1 1/4-7	42	35	248	63	-	99	85	65	185	1,125	1,5	35
27791-05-1150AFX235	A	150	1 1/4-7	42	35	298	63	-	99	85	65	235	1,125	1,5	35