


## Item description/product images

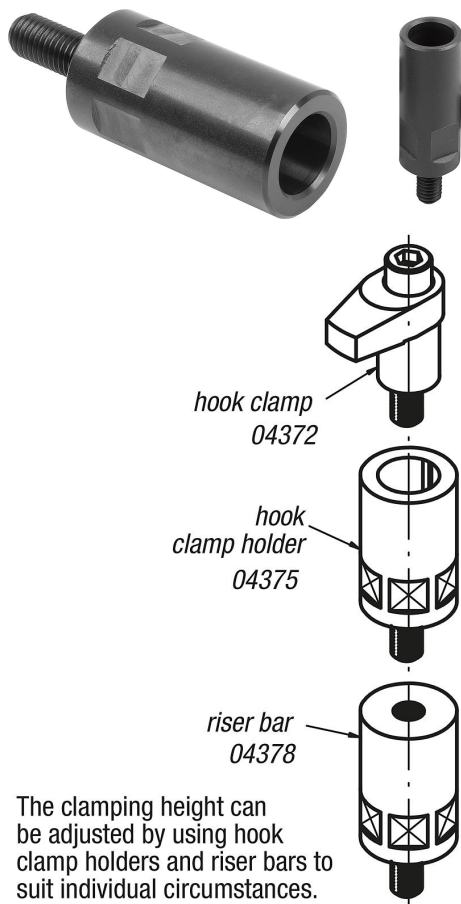

The clamping height can be adjusted by using hook clamp holders and riser bars to suit individual circumstances.

## Description


**Material:**  
Carbon steel.

**Version:**  
Black oxidised.

**Note:**  
Hook clamp holders are for holding and raising hook clamps.

**Accessory:**  
Hook clamps 04372.  
Extensions for jack screws 04378.

## Drawings

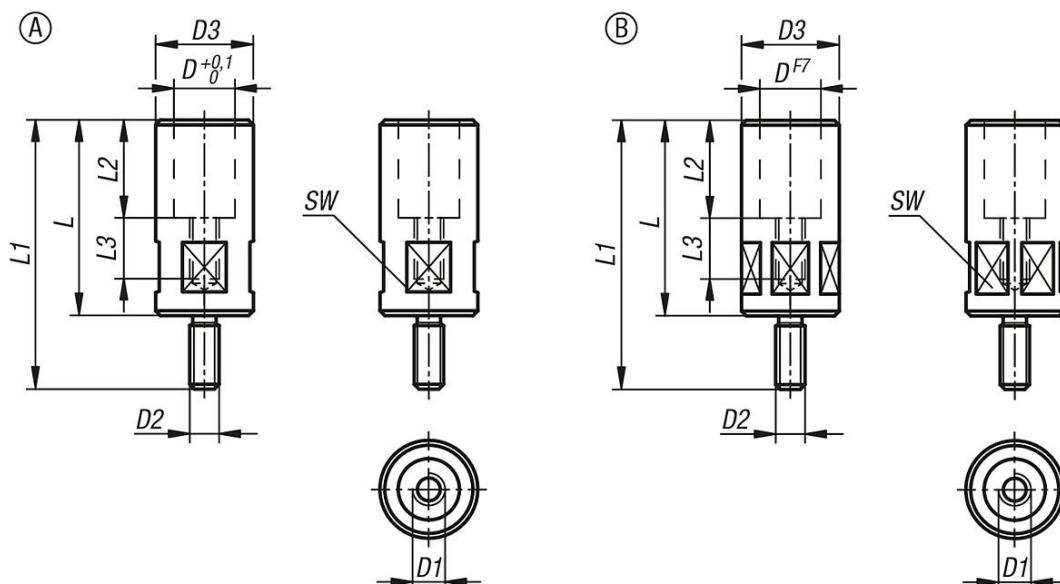

## Overview of items

| Order No.   | Form | Form definition | D  | D1 | D2 | D3 | L  | L1 | L2 | L3 | SW | Tightening torque max. Nm |
|-------------|------|-----------------|----|----|----|----|----|----|----|----|----|---------------------------|
| 04375-04035 | A    | Parallel        | 10 | M4 | M6 | 14 | 35 | 46 | 16 | 13 | 12 | 2,7                       |

## Overview of items

| Order No.   | Form | Form definition           | D  | D1  | D2  | D3 | L   | L1  | L2 | L3 | SW | Tightening torque max. Nm |
|-------------|------|---------------------------|----|-----|-----|----|-----|-----|----|----|----|---------------------------|
| 04375-06040 | A    | Parallel                  | 12 | M6  | M8  | 16 | 40  | 54  | 19 | 14 | 13 | 7                         |
| 04375-08055 | B    | Dangerous goods class 8+9 | 18 | M8  | M8  | 24 | 55  | 74  | 25 | 20 | 22 | 29,4                      |
| 04375-10063 | B    | Dangerous goods class 8+9 | 20 | M10 | M12 | 32 | 63  | 93  | 30 | 21 | 30 | 39,2                      |
| 04375-10080 | B    | Dangerous goods class 8+9 | 20 | M10 | M12 | 32 | 80  | 110 | 30 | 23 | 30 | 39,2                      |
| 04375-12080 | B    | Dangerous goods class 8+9 | 25 | M12 | M12 | 40 | 80  | 110 | 40 | 25 | 36 | 49                        |
| 04375-12100 | B    | Dangerous goods class 8+9 | 25 | M12 | M12 | 40 | 100 | 130 | 40 | 28 | 36 | 49                        |
| 04375-16080 | B    | Dangerous goods class 8+9 | 32 | M16 | M16 | 50 | 80  | 110 | 40 | 25 | 46 | 78,4                      |
| 04375-16100 | B    | Dangerous goods class 8+9 | 32 | M16 | M16 | 50 | 100 | 130 | 40 | 28 | 46 | 78,4                      |