

Description de l'article/illustrations du produit



Description

Matière :


Acier de traitement.

Finition :

Traité et bruni.

Diamètre ajusté rectifié.

Dessins

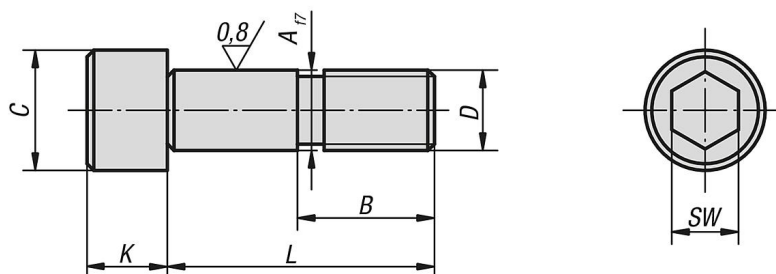

Aperçu des articles

Référence	Forme	A	B	C	D	K	L	SW	Couple de serrage max. Nm
07533-112045	A	12	22	18	M12	12	45	10	88
07533-112055	A	12	22	18	M12	12	55	10	88
07533-112065	A	12	22	18	M12	12	65	10	88
07533-112075	A	12	22	18	M12	12	75	10	88
07533-116055	A	16	25	24	M16	16	55	14	216
07533-116065	A	16	25	24	M16	16	65	14	216
07533-116075	A	16	25	24	M16	16	75	14	216