



## Item description/product images

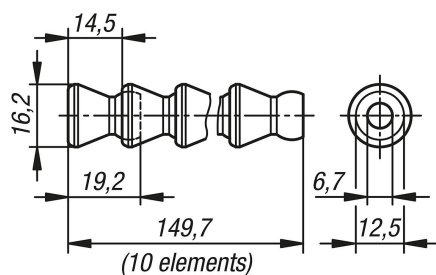


1/4"



1/2"

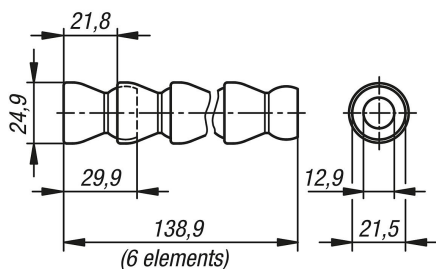

3/4"

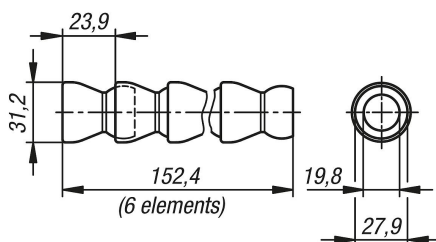

## Description

**Material:**

Polyoxymethylene (POM).

**Version:**

Flexible hose blue or black.

Accessories orange.

**Note:**

The flexible hose is used to direct liquids or extract liquids, dust, steam or smoke. It can be extended and shortened as needed. The material is resistant to most chemicals and solvents. It is not electrically conductive, so it is also suitable for use on EDM's.

Precise adjustment, vibration resistant, position reliability, pressure stability. Freely combinable with nozzles, fasteners, junctions, T-pieces, reducers, extensions etc.

**Recommended line pressure:**

Size 1/4" 2 - 3.5 bar

Size 1/2" 1.4 - 2 bar

Size 3/4" 0.7 - 1.4 bar

**Flow rate:**

Size 1/4" 950 l/min.

Size 1/2" 1800 l/min.

Size 3/4" 4300 l/min.

**Temperature range:**

-20 °C to +80 °C.

Item description/product images



Drawings



Overview of items

