

## Item description/product images

**Description**


**Material:**  
Polyamide PA6.

**Version:**  
black.


**Note:**  
The low-friction cable guide enables the energy chain/corrugated pipe to run smoothly and evenly through the guide.

**Temperature range:**  
-45 °C to +105 °C (briefly up to +150 °C).

**Assembly:**  
The low-friction guide is opened and closed tool-free via a plastic latch. The inner jaws consist of two identical half shells that are fitted on the energy chain via hole-pin connections. The jaws fitted around the energy chain are inserted into the connecting element and ensure that the energy chain runs smoothly.

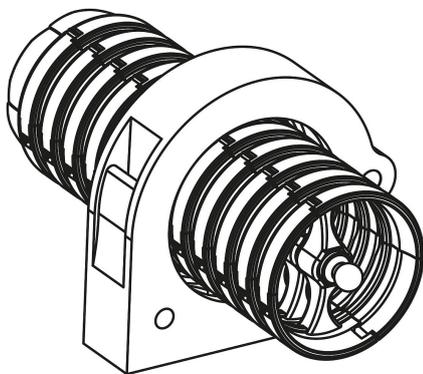

## Drawings

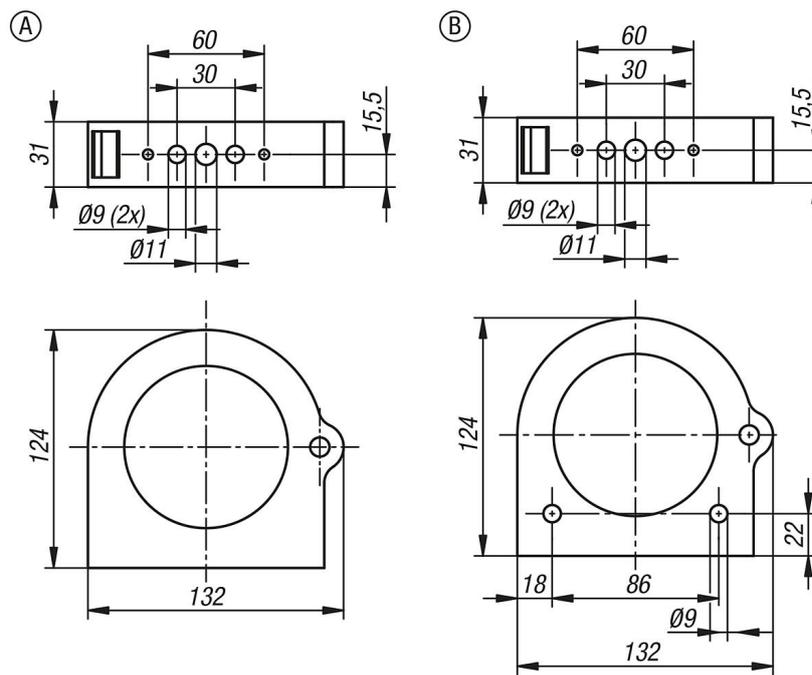

## Overview of items

Order No.	Form	Form definition	Nominal size
80855-08-07011	A	standard	70
80855-08-07021	B	front fastening	70