

## Item description/product images



## Description

## Product description:

Retaining cables are used to secure loose components to appliances or fixtures. The different types offer a wide range of attachment and freedom of movement options. A4 stainless steel retaining cables are recommended for applications needing very high corrosion resistance.

## Material:

Standard version:

Retaining cable stainless steel 1.4301.

Clip and crimp terminal aluminium or stainless steel 1.4301.

Stainless steel version A4:

Retaining cable stainless steel 1.4401.

Clip and crimp terminal stainless steel 1.4401.

## Version:

Retaining cable bright or with transparent or black plastic sleeve.

## Application:

For securing loose tools or other components to appliances and equipment.


## Temperature range:

max. 80°C.

## Accessory:

With the retaining cable and key ring (03199) the ball lock pins (03193, 03194, 03196, 03415, 03415-05, 03415-10, 03418, 03418-10, 03420, 03420-05, 03420-10, 03422) can be secured so that they cannot be lost.

## Drawings

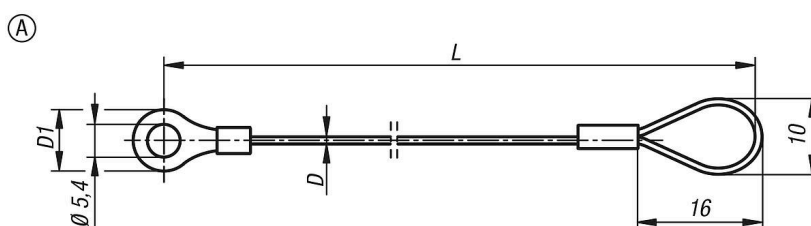

## Overview of items

Order No.	Form	Form definition	Steel key	Surface finish body	Main colour	Material	Surface finish	Material	Surface finish	L	D=rope diameter	D1
03199-01001	A	with eye and crimp terminal	1.4301	bright	-	Aluminium	bright	Aluminium	bright	100	1,6	9,3
03199-01501	A	with eye and crimp terminal	1.4301	bright	-	Aluminium	bright	Aluminium	bright	150	1,6	9,3
03199-02001	A	with eye and crimp terminal	1.4301	bright	-	Aluminium	bright	Aluminium	bright	200	1,6	9,3
03199-03001	A	with eye and crimp terminal	1.4301	bright	-	Aluminium	bright	Aluminium	bright	300	1,6	9,3
03199-05001	A	with eye and crimp terminal	1.4301	bright	-	Aluminium	bright	Aluminium	bright	500	1,6	9,3
03199-0100	A	with eye and crimp terminal	1.4301	plastic cover	transparent	Aluminium	bright	Aluminium	bright	100	1,6	11,5
03199-0150	A	with eye and crimp terminal	1.4301	plastic cover	transparent	Aluminium	bright	Aluminium	bright	150	1,6	11,5
03199-0200	A	with eye and crimp terminal	1.4301	plastic cover	transparent	Aluminium	bright	Aluminium	bright	200	1,6	11,5
03199-0300	A	with eye and crimp terminal	1.4301	plastic cover	transparent	Aluminium	bright	Aluminium	bright	300	1,6	11,5
03199-0500	A	with eye and crimp terminal	1.4301	plastic cover	transparent	Aluminium	bright	Aluminium	bright	500	1,6	11,5
03199-01002	A	with eye and crimp terminal	1.4301	plastic cover	transparent	Stainless steel	bright	Stainless steel	bright	100	1,6	9,3
03199-01502	A	with eye and crimp terminal	1.4301	plastic cover	transparent	Stainless steel	bright	Stainless steel	bright	150	1,6	9,3
03199-02002	A	with eye and crimp terminal	1.4301	plastic cover	transparent	Stainless steel	bright	Stainless steel	bright	200	1,6	9,3
03199-03002	A	with eye and crimp terminal	1.4301	plastic cover	transparent	Stainless steel	bright	Stainless steel	bright	300	1,6	9,3

## Overview of items

Order No.	Form	Form definition	Steel key	Surface finish body	Main colour	Material	Surface finish	Material	Surface finish	L	D=rope diameter	D1
03199-05002	A	with eye and crimp terminal	1.4301	plastic cover	transparent	Stainless steel	bright	Stainless steel	bright	500	1,6	9,3
03199-01004	A	with eye and crimp terminal	1.4401	plastic cover	transparent	Stainless steel	bright	Stainless steel	bright	100	1,6	9,3
03199-01504	A	with eye and crimp terminal	1.4401	plastic cover	transparent	Stainless steel	bright	Stainless steel	bright	150	1,6	9,3
03199-02004	A	with eye and crimp terminal	1.4401	plastic cover	transparent	Stainless steel	bright	Stainless steel	bright	200	1,6	9,3
03199-03004	A	with eye and crimp terminal	1.4401	plastic cover	transparent	Stainless steel	bright	Stainless steel	bright	300	1,6	9,3
03199-05004	A	with eye and crimp terminal	1.4401	plastic cover	transparent	Stainless steel	bright	Stainless steel	bright	500	1,6	9,3
03199-01003	A	with eye and crimp terminal	1.4301	plastic cover	black	Stainless steel	black passivated	Stainless steel	black passivated	100	1,6	9,3
03199-01503	A	with eye and crimp terminal	1.4301	plastic cover	black	Stainless steel	black passivated	Stainless steel	black passivated	150	1,6	9,3
03199-02003	A	with eye and crimp terminal	1.4301	plastic cover	black	Stainless steel	black passivated	Stainless steel	black passivated	200	1,6	9,3
03199-03003	A	with eye and crimp terminal	1.4301	plastic cover	black	Stainless steel	black passivated	Stainless steel	black passivated	300	1,6	9,3
03199-05003	A	with eye and crimp terminal	1.4301	plastic cover	black	Stainless steel	black passivated	Stainless steel	black passivated	500	1,6	9,3