

## Item description/product images



## Description

## Material:

Knobs thermoset PF 31.


Rod steel 1.0718 or stainless steel 1.4305.

## Version:

Thermoset black, high-gloss polished.

Steel black oxidised or bright stainless steel.

## Drawings

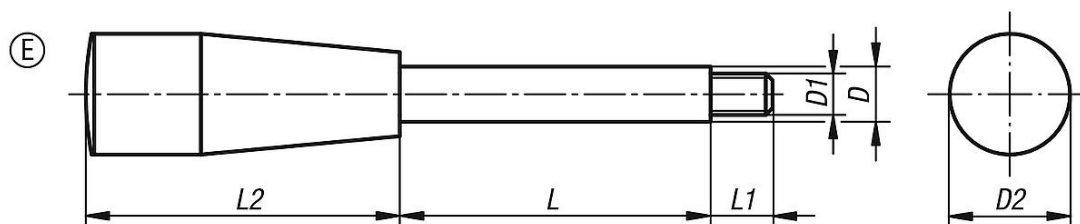

## Overview of items

| Order No.      | Version         | Form | D  | D1  | D2 | L   | L1 | L2 |
|----------------|-----------------|------|----|-----|----|-----|----|----|
| 06360-608X35   | steel           | E    | 8  | M6  | 17 | 35  | 9  | 45 |
| 06360-608X50   | steel           | E    | 8  | M6  | 17 | 50  | 9  | 45 |
| 06360-608X65   | steel           | E    | 8  | M6  | 17 | 65  | 9  | 45 |
| 06360-610X50   | steel           | E    | 10 | M8  | 23 | 50  | 13 | 61 |
| 06360-610X65   | steel           | E    | 10 | M8  | 23 | 65  | 13 | 61 |
| 06360-610X80   | steel           | E    | 10 | M8  | 23 | 80  | 13 | 61 |
| 06360-610X100  | steel           | E    | 10 | M8  | 23 | 100 | 13 | 61 |
| 06360-612X65   | steel           | E    | 12 | M10 | 29 | 65  | 15 | 71 |
| 06360-612X80   | steel           | E    | 12 | M10 | 29 | 80  | 15 | 71 |
| 06360-612X100  | steel           | E    | 12 | M10 | 29 | 100 | 15 | 71 |
| 06360-612X125  | steel           | E    | 12 | M10 | 29 | 125 | 15 | 71 |
| 06360-614X80   | steel           | E    | 14 | M12 | 29 | 80  | 16 | 71 |
| 06360-614X100  | steel           | E    | 14 | M12 | 29 | 100 | 16 | 71 |
| 06360-614X125  | steel           | E    | 14 | M12 | 29 | 125 | 16 | 71 |
| 06360-614X160  | steel           | E    | 14 | M12 | 29 | 160 | 16 | 71 |
| 06360-1608X35  | stainless steel | E    | 8  | M6  | 17 | 35  | 9  | 45 |
| 06360-1608X50  | stainless steel | E    | 8  | M6  | 17 | 50  | 9  | 45 |
| 06360-1608X65  | stainless steel | E    | 8  | M6  | 17 | 65  | 9  | 45 |
| 06360-1610X50  | stainless steel | E    | 10 | M8  | 23 | 50  | 13 | 61 |
| 06360-1610X65  | stainless steel | E    | 10 | M8  | 23 | 65  | 13 | 61 |
| 06360-1610X80  | stainless steel | E    | 10 | M8  | 23 | 80  | 13 | 61 |
| 06360-1610X100 | stainless steel | E    | 10 | M8  | 23 | 100 | 13 | 61 |
| 06360-1612X65  | stainless steel | E    | 12 | M10 | 29 | 65  | 15 | 71 |
| 06360-1612X80  | stainless steel | E    | 12 | M10 | 29 | 80  | 15 | 71 |
| 06360-1612X100 | stainless steel | E    | 12 | M10 | 29 | 100 | 15 | 71 |
| 06360-1612X125 | stainless steel | E    | 12 | M10 | 29 | 125 | 15 | 71 |
| 06360-1614X80  | stainless steel | E    | 14 | M12 | 29 | 80  | 16 | 71 |
| 06360-1614X100 | stainless steel | E    | 14 | M12 | 29 | 100 | 16 | 71 |
| 06360-1614X125 | stainless steel | E    | 14 | M12 | 29 | 125 | 16 | 71 |
| 06360-1614X160 | stainless steel | E    | 14 | M12 | 29 | 160 | 16 | 71 |

