

Item description/product images



Description

Material:

Steel or 1.4301 stainless steel.
Tension spring stainless steel.

Version:

Steel bright or electro zinc-plated.
Stainless steel bright.

Note:

Butt type hinges.
Opening angle 270°.


Spring torque:

M(0°): 0.84 Nm / M(90°): 1.68 Nm / M(180°): 2.55 Nm


Form A: without holes

Form B: with holes

Drawings

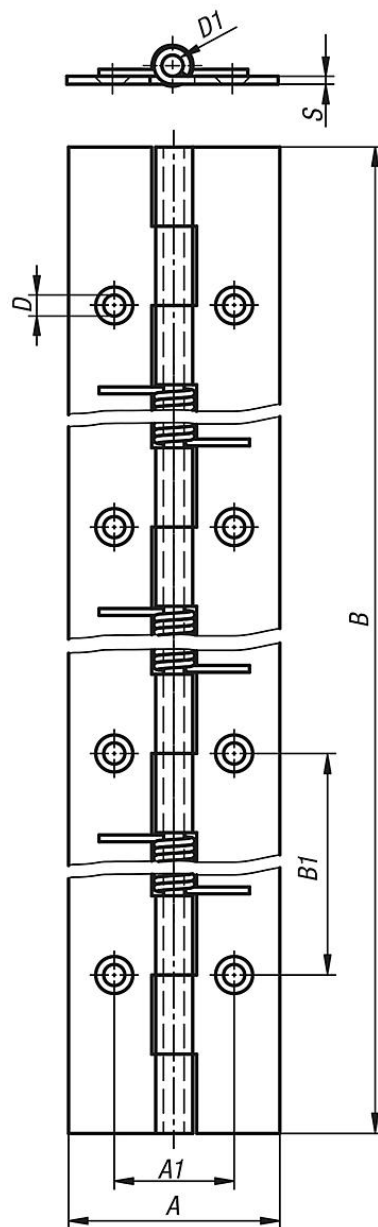

Hinges with closing spring

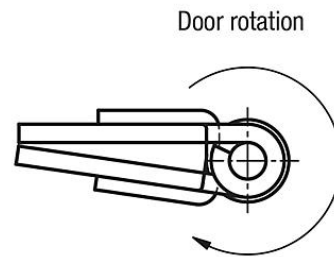

Overview of items

Order No.	Form	Version 1	Main material	Main colour	A	A1	B	B1	D	D1	S
27904-4024010	A	spring closed	steel	bright	40	-	240	-	-	4	1,5
27904-4024011	B	spring closed	steel	galvanised	40	22,7	240	60	4	4	1,5
27904-14024010	A	spring closed	stainless steel	bright	40	-	240	-	-	4	1,5
27904-14024011	B	spring closed	stainless steel	bright	40	22,7	240	60	4	4	1,5